


# Sprinkler HI-FOG® 2000 Type C20-xxC/3

Stock codes C-0001936, C-0001937 and C61511/3

TECHNICAL DATA SHEET K0006970 REVISION - DATE 25 Jan 2012

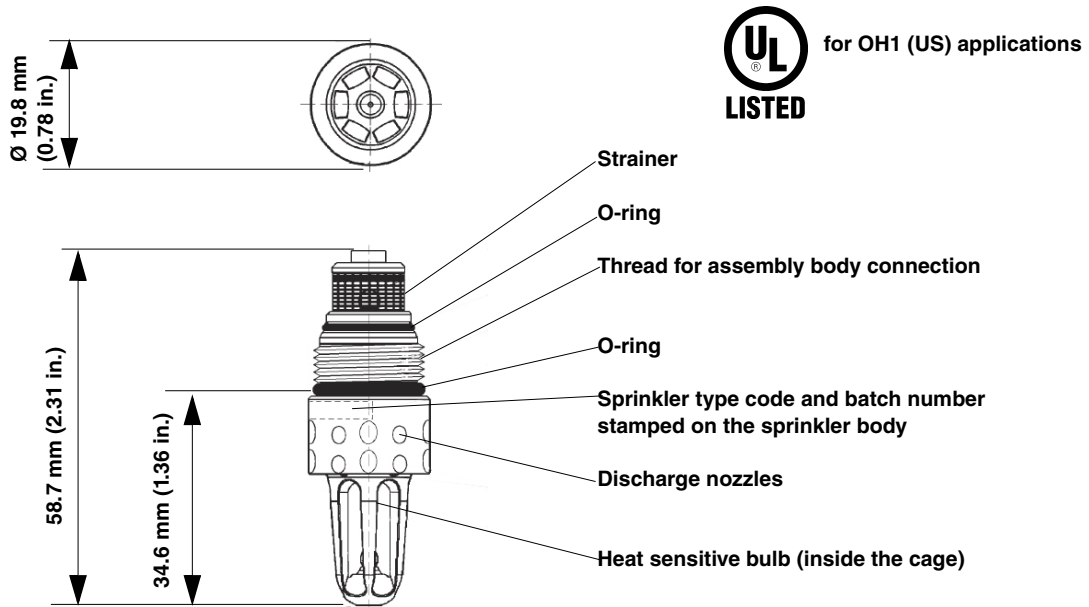

Products	Stock code	Type	Heat sensitive bulb
	C-0001936	C20-57C/3	57°C (135°F) (orange color)
	C61511/3	C20-68C/3	68°C (155°F) (red color)
	C-0001937	C20-79C/3	79°C (175°F) (yellow color)*

\*) Temperature rating 79°C (175°F) is permitted only near sources of elevated temperature, i.e. space heaters.

General	Body material	Brass	
	Finish	Nickel	
	Mass	0.058 kg	2.05 oz
	K-factor	4.1 lpm/bar <sup>0.5</sup>	0.28 gpm/psi <sup>0.5</sup>
Installation	Location	Ceiling	
	Projection	Pendent	
	Max. ceiling height	4 m	13.1 ft.
	Max. / Min. spacing	3.05 m / 1.83 m	10 ft. / 6 ft.
	Max. distance from walls	1.53 m	5 ft.
	Operating pressure range	80-130 bar	1160-1885 psi
	Min. distance from the top of any stored material to the tip of the sprinkler	533 mm	21 in.