


# Kidde Fire Systems HPCO2 Component Description



## Nitrogen Pilot Cylinder, Bracket, and Adapter

Effective: April 2022  
K-81-5050 Rev AC

P/N: WK-877940-000, WK-877845-00, and WK-699205-010

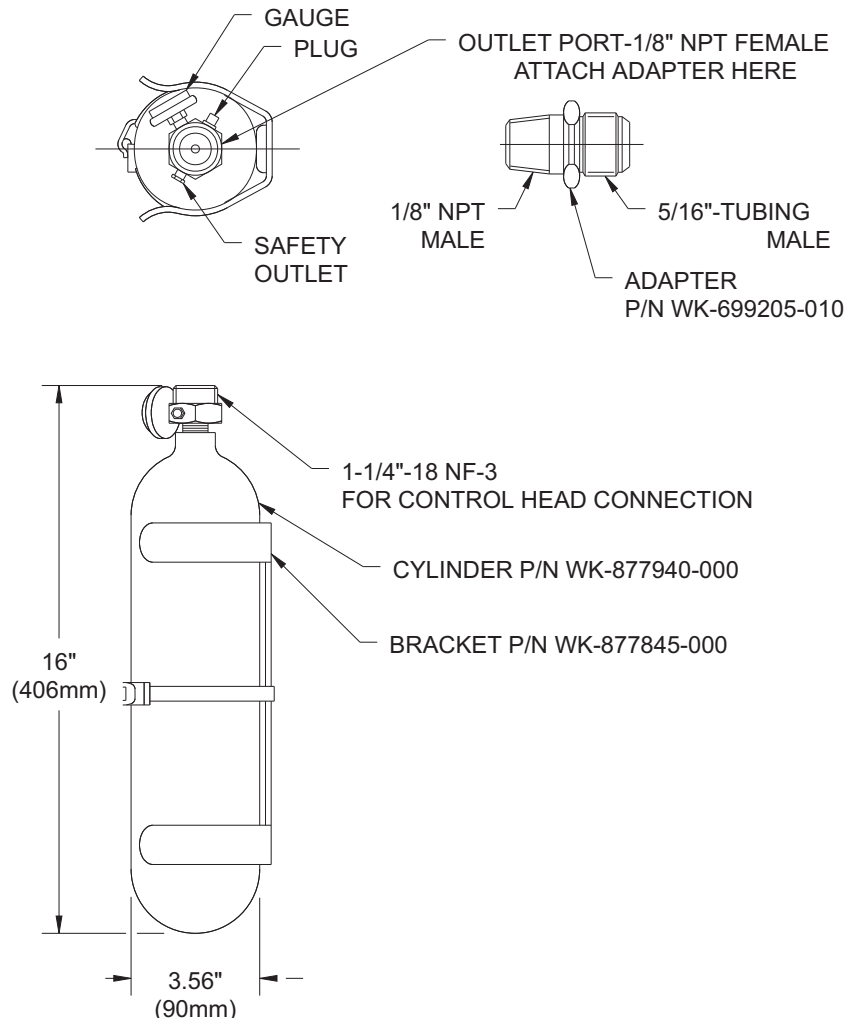

### MATERIALS

- Cylinder: Steel, Painted Black
- Valve: Brass
- Bracket: Steel, Painted Black
- Adapter: Brass
- Body and Piston: Brass

### SPECIFICATIONS

- Cylinder Capacity - 108 IN3 (1770 CM3)
- Safety Outlet Burst Range - 2650-3000 psi (183-207 BAR) AT 70°F (20°C)
- Nitrogen: BB-n-411b Grade A, Type I 1800 psi (124 BAR) AT 70°F (20°C)

### EXPORT INFORMATION (USA)

Jurisdiction: EAR  
Classification: EAR99

This document contains technical data subject to the EAR.

All trademarks are the property of their respective owners.

©2022 Carrier

This literature is provided for informational purposes only. KIDDE-FENWAL, INC. believes this data to be accurate, but it is published and presented without any guarantee or warranty whatsoever. KIDDE-FENWAL, INC. assumes no responsibility for the product's suitability for a particular application. The fire suppression system design, installation, maintenance, service and troubleshooting must be performed by trained, authorized Kidde Fire Systems distributors for the product to work correctly. If you need more information on this product, or if you have a particular problem or question, contact KIDDE-FENWAL, INC., Ashland, MA 01721 USA. Telephone: (508) 881-2000.

Kidde Fire Systems  
400 Main Street  
Ashland, MA 01721  
Ph: 508.881.2000  
Fax: 508.881.8920  
[kiddefiresystems.com](http://kiddefiresystems.com)